

# Technical data sheet

## Service pole, type ISSDM45F

Item number: 6289974



ISS aluminium service pole with a flexible hose to the ceiling, 45 mm system opening.

Set consisting of:

1 two-tube service pole with 2 flexible hoses to the ceiling

Total length: 2,300 mm

2 flexible hoses, length each 1,500 mm Ø 30 mm

2 covers, aluminium. length 2,300 mm

There are two 45 mm system openings on opposite sides for direct installation of Module 45® devices and plug-in devices. The floor plate as a stand, type SFISSF, and the hose connection to the ceiling, type SAISSF, should be ordered separately (see articles below).



**Alu** Aluminium

### Master data

|                                    |                            |
|------------------------------------|----------------------------|
| Item number                        | 6289974                    |
| Type                               | ISSDM45FRW                 |
| Description 1                      | Service pole               |
| Description 2                      | floor/ceiling with hose    |
| Manufacturer                       | OBO                        |
| Dimension                          | 2300x80x130                |
| Colour                             | Pure white; RAL 9010       |
| Material                           | Aluminium                  |
| Smallest sales unit                | 1                          |
| Unit of quantity                   | Piece                      |
| Weight                             | 871 kg                     |
| Weight unit                        | kg/100 pc.                 |
| CO2 Footprint (GWP) Cradle-to-Gate | 140,9507 kg CO2e / 1 Piece |


# Technical data sheet

Service pole, type ISSDM45F


Item number: 6289974



## Dimensions

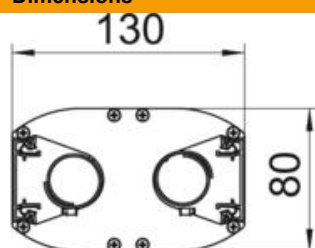

|        |          |
|--------|----------|
| Length | 2,300 mm |
| Width  | 80 mm    |
| Height | 130 mm   |

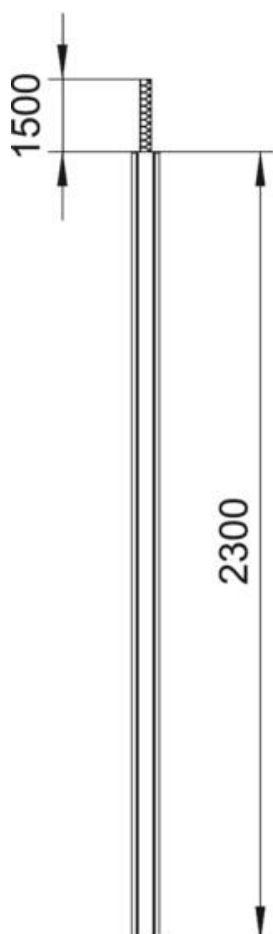

# Technical data sheet

Service pole, type ISSDM45F

Item number: 6289974



## Technical data

|                               |              |
|-------------------------------|--------------|
| Number of usable covers       | 2            |
| Number of compartments        | 2 St.        |
| Version for                   | Double-sided |
| Fastening type                | Stand        |
| Floor mounting                | yes          |
| Ceiling mounting              | yes          |
| Continuous profile            | yes          |
| Halogen-free                  | yes          |
| Height compensation, max.     | 1500 mm      |
| Height compensation, min.     | 0 mm         |
| Cable entry                   | Top          |
| Cover width                   | 45 mm        |
| Changes according to location | yes          |
| Pole shape                    | Oval         |
| Pole height, max.             | 3800 mm      |
| Pole height, min.             | 2300 mm      |
| Adjustable                    | yes          |
| Pre-wired                     | no           |