 


Technical data sheet

Service pole, type ISSRHSM45

Item number: 6290090



ISS aluminium service pole with a 45 mm system opening.

Set consisting of:

 
1 one-compartment pole with stand

Total length: 675 mm

1 aluminium cover

Length: 675 mm

The design of this ISS service pole is based on an extremely slender, round aluminium profile, which has a smooth cover of the Rapid 45 device installation trunking series on the front side. The 45 mm system opening is suitable for direct acceptance of Modul 45® switching and connection devices. The installation compartment is theoretically sufficient for 14 Modul 45® devices. If Modul 45connect® is used or in the case of cabling requiring a lot of space, the number of the max. installable devices is reduced. There is the option of installing a partition, type 2371/40 (6023096).



Alu

Aluminium

Master data

Item number	6290090
Type	ISSRHSM45RW
Description 1	Service pole
Description 2	floor
Manufacturer	OBO
Dimension	675x70x60
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	135 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	15,009 kg CO2e / 1 Piece


Technical data sheet

Service pole, type ISSRHSM45


Item number: 6290090



Dimensions

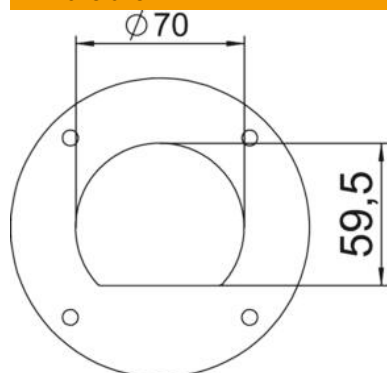

Length	675 mm
Width	70 mm
Height	59.5 mm

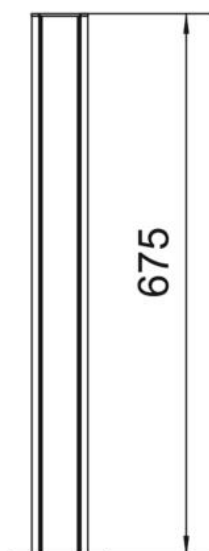

Technical data sheet

Service pole, type ISSRHSM45

Item number: 6290090



Technical data

Number of usable covers	1
Number of compartments	1 St.
Version for	Single-sided
Fastening type	Stand
Floor mounting	yes
Ceiling mounting	no
Continuous profile	yes
Halogen-free	yes
Cable entry	Bottom
Cover width	45 mm
Changes according to location	no
Pole shape	Round
Pole height, min.	675 mm
Adjustable	no
Pre-wired	no