

Technical data sheet

Service pole, type ISSRM45F

Item number: 6290095



ISS aluminium service pole with a flexible hose to the ceiling, 45 mm system opening.

Set consisting of:

1 single-tube pole with flexible hose to the ceiling

Total length: 2,300 mm

1 flexible hose, length: 1,500 mm Ø 30 mm

1 cover, aluminium, length: 2,300 mm

The design of the ISS service pole is based on an extremely slim and round aluminium profile that to the front side shows a smooth cover of the Rapid 45 device installation series. The 45 mm system opening is suitable for direct acceptance of Modul 45® switching and connection devices.

The floor plate as a stand, type SFISSF, and the hose connection to the ceiling, type SAISSF, should be ordered separately (see articles below).



Alu Aluminium

Master data

Item number	6290095
Type	ISSRM45FRW
Description 1	Service pole
Description 2	floor/ceiling with hose
Manufacturer	OBO
Dimension	2300x70x59
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	380 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	58,0164 kg CO2e / 1 Piece


Technical data sheet

Service pole, type ISSRM45F

Item number: 6290095



Dimensions

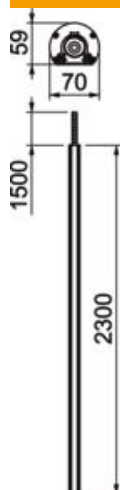

Length	2,300 mm
Width	70 mm
Height	59 mm

Technical data

Number of usable covers	1
Number of compartments	1 St.
Version for	Single-sided
Fastening type	Stand
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	yes
Halogen-free	yes
Height compensation, max.	1500 mm
Height compensation, min.	0 mm
Cable entry	Top
Cover width	45 mm
Changes according to location	yes
Pole shape	Round
Pole height, max.	3800 mm
Pole height, min.	2300 mm
Adjustable	yes
Pre-wired	no