


# Technical data sheet

## Floor plate for ISS140100R

Item number: 6290337



Floor plate to fasten the ISS140100R on the floor. The floor plate with a visible edge has four fastening holes Ø 8.5 mm.

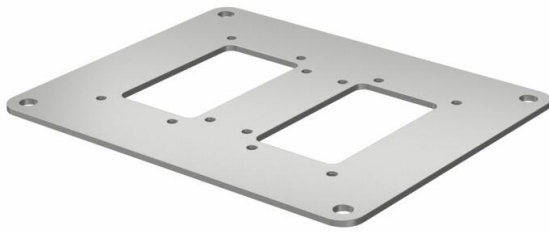

Steel



Strip galvanised / plastic coated

### Master data

|                                    |                                   |
|------------------------------------|-----------------------------------|
| Item number                        | 6290337                           |
| Type                               | ISSBP140100WA                     |
| Description 1                      | Floor plate                       |
| Description 2                      | for ISS140100R                    |
| Manufacturer                       | OBO                               |
| Dimension                          | 200x160x3                         |
| Colour                             | White aluminium; RAL 9006         |
| Material                           | Steel                             |
| Surface                            | Strip galvanised / plastic coated |
| Surface standard                   | DIN EN 10346                      |
| Smallest sales unit                | 1                                 |
| Unit of quantity                   | Piece                             |
| Weight                             | 57.2 kg                           |
| Weight unit                        | kg/100 pc.                        |
| CO2 Footprint (GWP) Cradle-to-Gate | 2,6181 kg CO2e / 1 Piece          |


# Technical data sheet

## Floor plate for ISS140100R

Item number: 6290337



### Dimensions

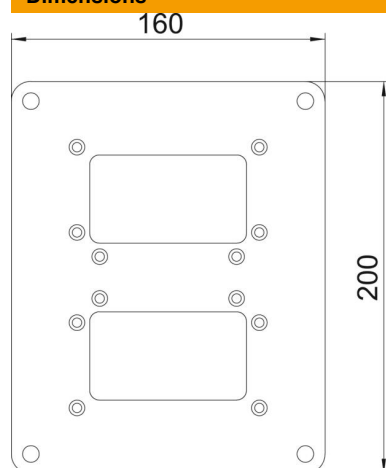

|        |        |
|--------|--------|
| Length | 200 mm |
| Width  | 160 mm |
| Height | 3 mm   |

### Technical data

|              |     |
|--------------|-----|
| xxxxx.       | no  |
| Halogen-free | yes |