

Technical data sheet

US 7 support FT

Item number: 6340016



U support in fixed lengths. Dimensions 70 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 61.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6340016
Type	US 7 20 FT
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	70x50x200
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	81 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,0753 kg CO2e / 1 Piece


Technical data sheet

US 7 support FT


Item number: 6340016



Dimensions

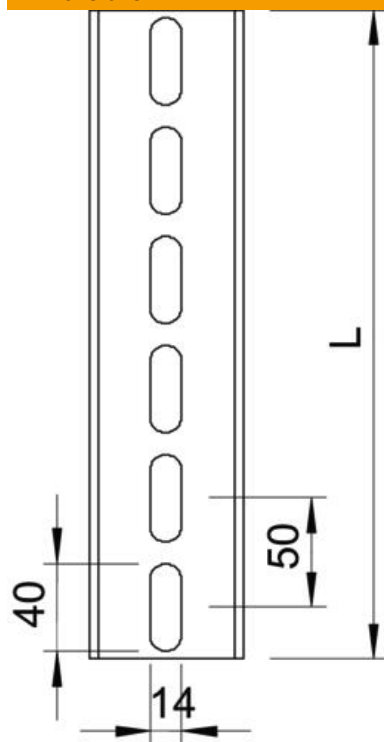

Dimension	70 x 50 x 4
Length	200 mm
Width	70 mm
Height	50 mm
Dimension L	200 mm

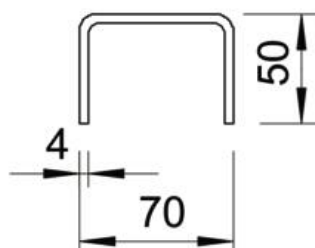

Technical data sheet

US 7 support FT

Item number: 6340016



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
EPD article	yes
Maintain electrical functions	yes
Hole width	14 mm
Material thickness	4 mm
With toothing	no
Profile shape	U profile
Slot width	62 mm
Static value A	4.59 cm ²
Static value I _y	13.79 cm ⁴
Static value I _z	36.84 cm ⁴
Static value W _y	4.11 cm ³
Static value W _z	10.53 cm ³