

Technical data sheet

US 5 support FT

Item number: 6340903



U support in fixed lengths. Dimensions 50 x 50 mm.

For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 45.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6340903
Type	US 5 30 FT
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x50x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	72 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,7973 kg CO2e / 1 Piece


Technical data sheet

US 5 support FT

Item number: 6340903



Dimensions

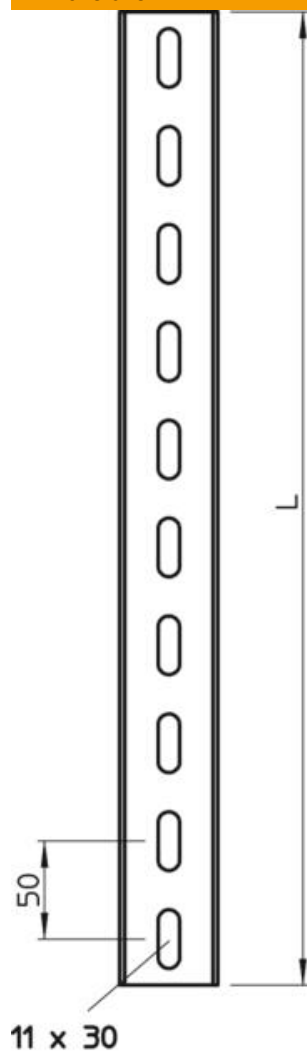

Dimension	50 x 50 x 2,5
Length	300 mm
Width	50 mm
Height	50 mm
Dimension L	300 mm

Technical data sheet

US 5 support FT

Item number: 6340903



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
EPD article	yes
Maintain electrical functions	yes
Material thickness	2.5 mm
With toothing	no
Profile shape	U profile
Slot width	45 mm
Static value A	2.74 cm ²
Static value I _y	8.32 cm ⁴
Static value I _z	12.53 cm ⁴
Static value W _y	2.61 cm ³
Static value W _z	5.01 cm ³