

Technical data sheet

US 7 support A2

Item number: 6341721



U support in fixed lengths. Dimensions 70 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 61.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6341721
Type	US 7 20 A2
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	70x50x200
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	78.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,7774 kg CO2e / 1 Piece


Technical data sheet

US 7 support A2


Item number: 6341721



Dimensions

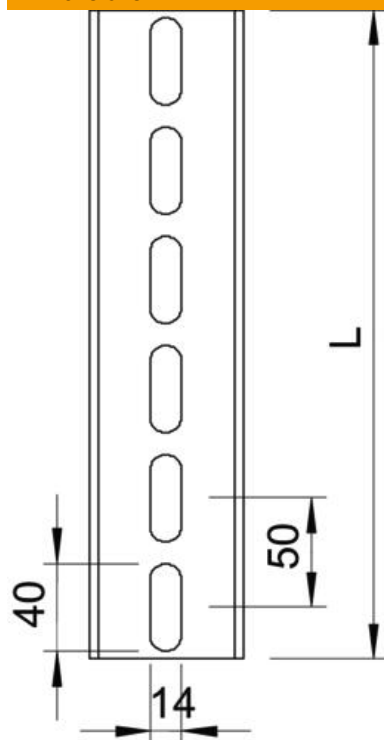

Dimension	70 x 50 x 4
Length	200 mm
Width	70 mm
Height	50 mm

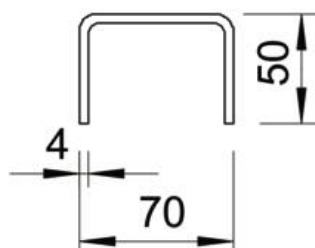

Technical data sheet

US 7 support A2

Item number: 6341721



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	no
Hole width	14 mm
Material thickness	4 mm
With toothing	no
Profile shape	U profile
ROHS-conformant	yes
Slot width	40 mm
Static value A	4.59 cm ²
Static value Iy	13.79 cm ⁴
Static value Iz	36.84 cm ⁴
Static value Wy	4.11 cm ³
Static value Wz	10.53 cm ³