

Technical data sheet

US 3 support FS

Item number: 6342302



U support in fixed lengths. Dimensions 30 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 25.



St Steel

FS Strip galvanised

Master data

Item number	6342302
Type	US 3 20 FS
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x30x200
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	25 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7531 kg CO2e / 1 Piece


Technical data sheet

US 3 support FS

Item number: 6342302



Dimensions

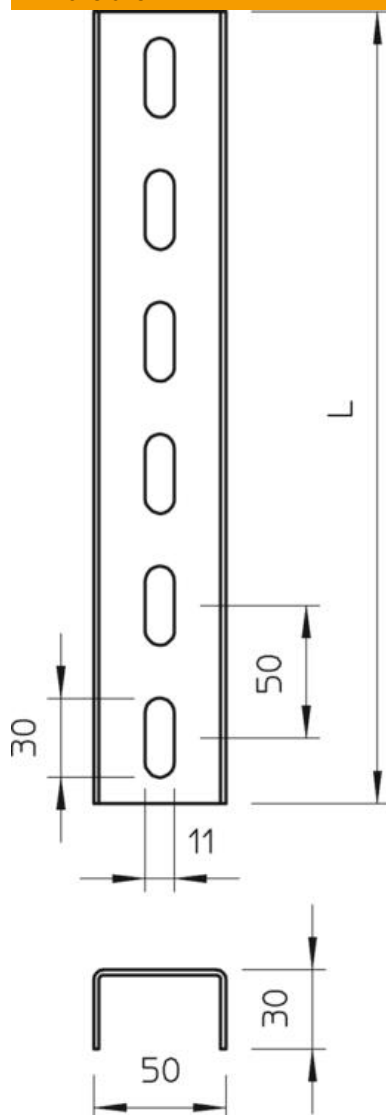

Dimension	30 x 50 x 2,0
Length	200 mm
Width	50 mm
Height	30 mm
Dimension L	200 mm

Technical data sheet

US 3 support FS

Item number: 6342302



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	yes
Hole width	11 mm
Material thickness	2 mm
With toothing	no
Profile shape	U profile
Slot width	30 mm
Static value A	1.42 cm ²
Static value I _y	1.52 cm ⁴
Static value I _z	5.72 cm ⁴
Static value W _y	0.7 cm ³
Static value W _z	2.29 cm ³