

Technical data sheet

US 3 support FT

Item number: 6342450



U support in fixed lengths. Dimensions 30 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 25.



St Steel

FT Hot-dip galvanised

Master data

Item number	6342450
Type	US 3 600 FT
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x30x6000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	834 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	19,9758 kg CO2e / 1 Piece


Technical data sheet

US 3 support FT

Item number: 6342450



Dimensions

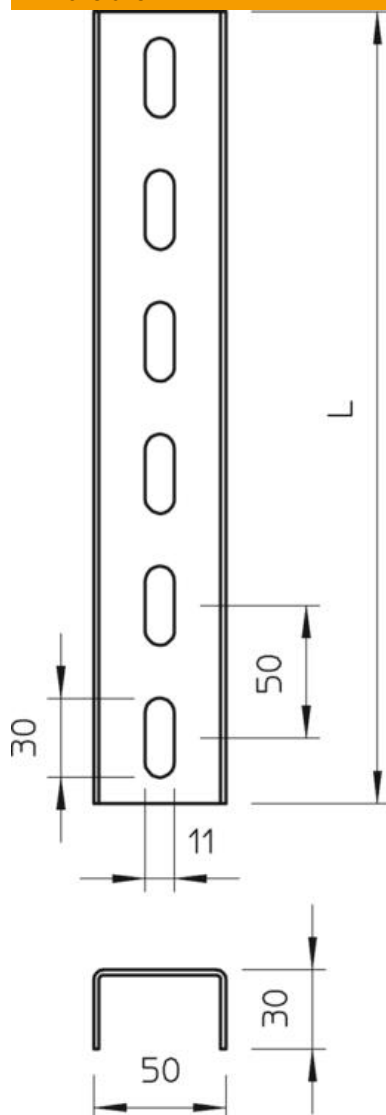

Dimension	30 x 50 x 2,5
Length	6,000 mm
Width	50 mm
Height	30 mm
Dimension L	6,000 mm

Technical data sheet

US 3 support FT

Item number: 6342450



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	no
Material thickness	2 mm
With toothing	no
Profile shape	U profile
ROHS-conformant	yes
Static value A	1.42 cm ²
Static value Iy	1.52 cm ⁴
Static value Iz	5.72 cm ⁴
Static value Wy	0.7 cm ³
Static value Wz	2.29 cm ³