

Technical data sheet

US 3 support A2

Item number: 6342457



U support in fixed lengths. Dimensions 30 x 50 mm.
For bracket widths of 400 mm or more, or if the bracket is mounted at the end of a suspended support, we recommend the use of the spacer, type DSK 25.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6342457
Type	US 3 50 A2
Description 1	U support
Description 2	3-sided perforated
Manufacturer	OBO
Dimension	50x30x500
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	66 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,9584 kg CO2e / 1 Piece


Technical data sheet

US 3 support A2

Item number: 6342457



Dimensions

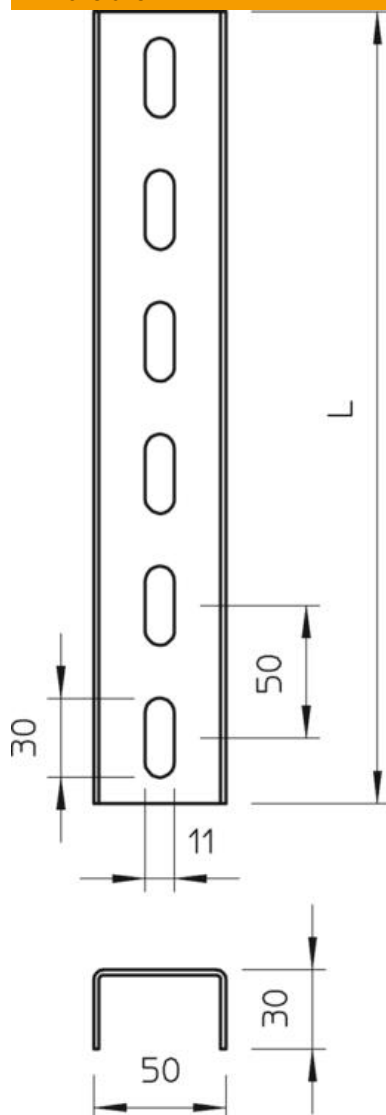

Dimension	30 x 50 x 2,0
Length	500 mm
Width	50 mm
Height	30 mm

Technical data sheet

US 3 support A2

Item number: 6342457



Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
Maintain electrical functions	no
Material thickness	2 mm
With toothing	no
Profile shape	U profile
ROHS-conformant	yes
Static value A	1.42 cm ²
Static value Iy	1.52 cm ⁴
Static value Iz	5.72 cm ⁴
Static value Wy	0.7 cm ³
Static value Wz	2.29 cm ³