

Technical data sheet

U support USL 5

Item number: 6344305



U support with perforations on three sides.
Screwless support bracket system. The connection between the head plate and the support and between the support and the brackets is implemented using splints. Rear perforation = 20 x 11 mm and slot and round hole d = 9 mm. Side perforation = Round hole 9 mm.



St	Steel
FS	Strip galvanised

Master data

Item number	6344305
Type	USL 5 200 FS
Description 1	U support
Description 2	for fastening with splint
Manufacturer	OBO
Dimension	51,5x29x2000
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	270.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	6,51 kg CO2e / 1 Piece


Technical data sheet

U support USL 5

Item number: 6344305



Dimensions

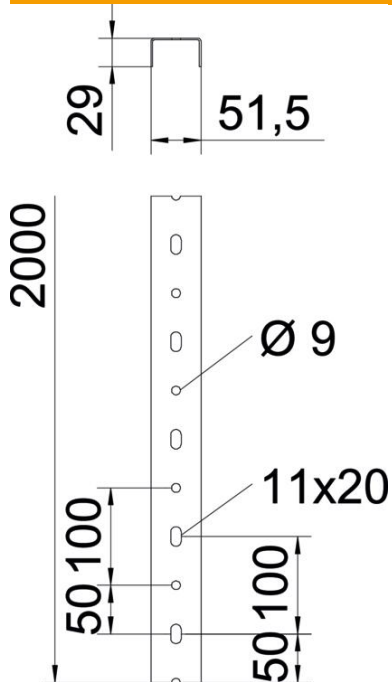

Dimension	2000 x 51,5 x 29
Length	2,000 mm
Width	51.5 mm
Height	29 mm
Dimension L	2,000 mm

Technical data

Breakable	no
Type of perforation	3 sides perforated
Version for	Single profile
EPD article	no
Maintain electrical functions	no
Material thickness	1.75 mm
With toothing	no
Profile shape	C profile
ROHS-conformant	yes