

Technical data sheet

KA-AW adapter plate

Item number: 6346725



Adapter plate with slots for universal fastening to vertical steel girders and walls. The bracket types AW 30, AW 55 ad AW 80 can be screwed to the adapter plate. ?Please order the hexagon head screw for bracket mounting (type SKS 12 x 40 GF) separately.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6346725
Type	KA-AW 55 FT
Description 1	Adapter plate
Description 2	for wall bracket
Manufacturer	OBO
Dimension	400x295x50
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	394.2 kg
Weight unit	kg/100 pc.


Technical data sheet

KA-AW adapter plate

Item number: 6346725



Dimensions

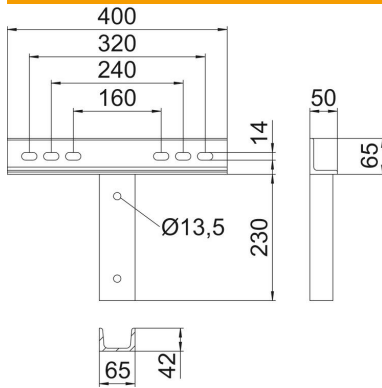

Length	50 mm
Width	400 mm
Height	230 mm
Dimension B	400 mm
Dimension H	230 mm
Dimension L	50 mm

Technical data

ROHS-conformant	yes
-----------------	-----