

Technical data sheet

Head plate, longitudinal

Item number: 6347053



Head plate for mounting on IS 8 support.
Including appropriate fastening material.

Limit the length of the support to max. 2,000 mm.



St Steel

FT Hot-dip galvanised

Master data

Item number	6347053
Type	KI 8 FT
Description 1	Head plate
Description 2	for IS 8 support
Manufacturer	OBO
Dimension	200mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	155 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,4015 kg CO2e / 1 Piece


Technical data sheet

Head plate, longitudinal

Item number: 6347053



Dimensions

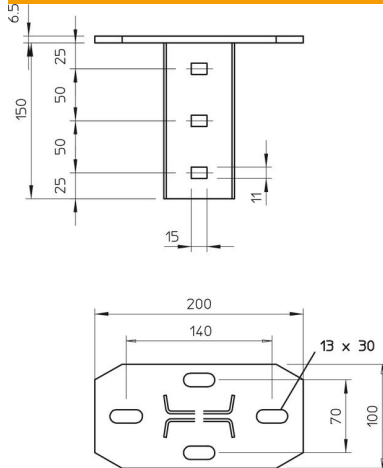

Length	200 mm
Width	100 mm
Height	156.5 mm

Technical data

Version for	Screw head plate
Suitable for ceiling fastening	yes
Suitable for panel fastening	no
Suitable for profile shapes	I profile
ROHS-conformant	yes
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm