

Technical data sheet

Head plate A4

Item number: 6348877



Head plate for mounting on US 3 supports.
The head plate can be mounted to fixed lengths of the U support, type US 3.
Including appropriate fastening material.
Including appropriate fastening material.



A4	Stainless steel
2B	Bright, treated

Master data

Item number	6348877
Type	KU 3 A4
Description 1	Head plate
Description 2	for US 3 support
Manufacturer	OBO
Dimension	130x40x100
Colour	stainless steel
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	40.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,6868 kg CO2e / 1 Piece


Technical data sheet

Head plate A4

Item number: 6348877



Dimensions

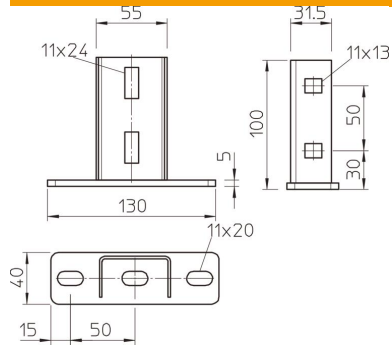

Length	130 mm
Width	40 mm
Height	100 mm

Technical data

Version for	Screw head plate
Maintain electrical functions	no
Suitable for ceiling fastening	yes
Suitable for panel fastening	no
Suitable for profile shapes	U profile
ROHS-conformant	yes
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm