

Technical data sheet

Head plate, light-duty version FT

Item number: 6349102



Light-duty head plate for mounting on US 7 support.
Please order fastening material (two hexagonal bolts SKS 12 x 100) separately.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6349102
Type	KU 7 FT
Description 1	Head plate
Description 2	for US 7 support
Manufacturer	OBO
Dimension	200x100
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	144.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,337 kg CO2e / 1 Piece


Technical data sheet

Head plate, light-duty version FT


Item number: 6349102



Dimensions

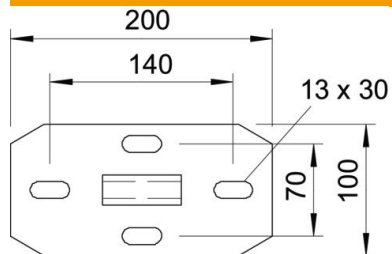

Length	200 mm
Width	100 mm
Height	121.5 mm

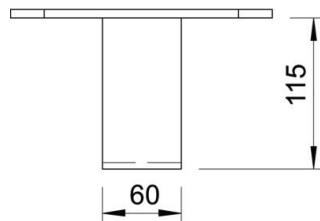

Technical data

Version for	Screw head plate
Suitable for ceiling fastening	yes
Suitable for panel fastening	no
Suitable for profile shapes	U profile
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm