

Technical data sheet

Clamping angle KWS FT

Item number: 6355218



Clamping angle, with hexagonal bolt, type KWS, for direct fixing of constructions to steel girder flanges.
Choose the clamping angle according to the thickness of the flange.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6355218
Type	KWS 5 FT
Description 1	Clamping profile
Description 2	with hexagon screw, h = 5 mm
Manufacturer	OBO
Dimension	60x50
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Pair
Weight	58.4 kg
Weight unit	kg/100 pairs
CO2 Footprint (GWP) Cradle-to-Gate	1,3012 kg CO2e / 2 Piece


Technical data sheet

Clamping angle KWS FT

Item number: 6355218



Dimensions

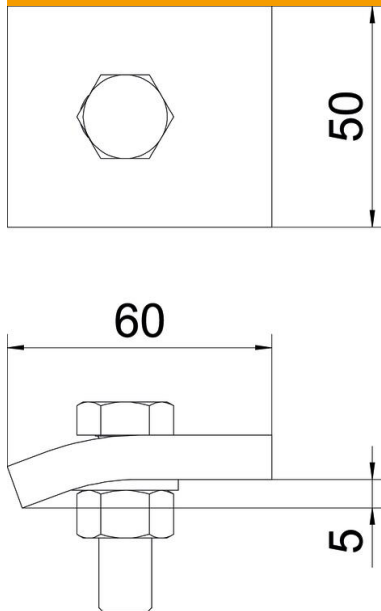

Height 5 mm

Technical data

F in kN	5.7 kN
Suitable for flange thickness, max.	8 mm
Suitable for flange thickness, min.	3 mm
Thread metric	12
ROHS-conformant	yes
Bolt	M12 x 40