

Technical data sheet

Chuck jaw, light-duty TKS A4

Item number: 6355837



Chuck jaw with hexagonal nut for direct fastening of structures to steel girders. The clamping range of the chuck jaw is limited to the maximum fastening thickness of 36 mm.



A4 Stainless steel

Master data

Item number	6355837
Type	TKS-L36 M12 A4
Description 1	Tensioning claw, light
Manufacturer	OBO
Dimension	M12x80
Colour	stainless steel
Material	Stainless steel 1.4571
Smallest sales unit	1
Unit of quantity	Piece
Weight	36 kg
Weight unit	kg/100 pc.


Technical data sheet

Chuck jaw, light-duty TKS A4

Item number: 6355837



Dimensions

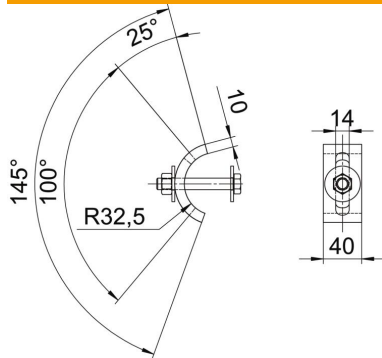

Height	36 mm
--------	-------

Technical data

F in kN	10 kN
Suitable for flange thickness, max.	36 mm
Suitable for flange thickness, min.	16 mm
Thread metric	12
ROHS-conformant	yes
Bolt	M12 x 80