

Technical data sheet

Ceiling bracket, trapezoidal FS

Item number: 6357506



Trapezoidal fastening for suspended mounting of cable support systems on standard trapezoidal ceilings.
Important: Observe the statics of the trapezoidal metal ceiling.
When using the holes provided, the trapezoidal fastening can be mounted onto a trapezoidal profile width of up to approx. 80 mm. Fastening takes place with the type TPB R lock or a hexagonal bolt of type SKS 10x110.
For fastening to trapezoidal ceilings. Scope of supply without bolt, type TPB/R.



St	Steel
FS	Strip galvanised

Master data

Item number	6357506
Type	TPB 100 FS
Description 1	Trapezoidal fastening
Manufacturer	OBO
Dimension	100x116
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	20
Unit of quantity	Piece
Weight	9.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2302 kg CO2e / 1 Piece


Technical data sheet

Ceiling bracket, trapezoidal FS

Item number: 6357506



Dimensions

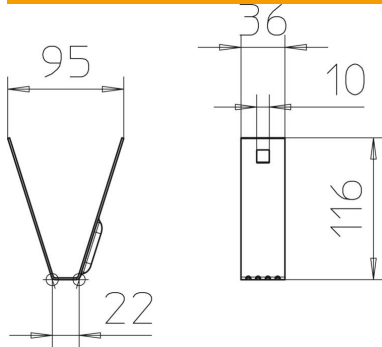

Length	36 mm
Width	100 mm
Height	116 mm

Technical data

F in kN	0.8 kN
Maintain electrical functions	no
Suitable for metric threaded rod	10
Material thickness	1.5 mm
ROHS-conformant	yes
Rustproof steel, pickled	no
Hinged	no
Adjustable	yes