

Technical data sheet

Ceiling bracket, trapezoidal A2

Item number: 6357516



Trapezoidal fastening for suspended mounting of cable support systems on standard trapezoidal ceilings.
Important: Observe the statics of the trapezoidal metal ceiling.
When using the holes provided, the trapezoidal fastening can be mounted onto a trapezoidal profile width of up to approx. 80 mm. Fastening takes place with the type TPB R lock or a hexagonal bolt of type SKS 10x110.
Scope of supply without bolt, type TPB/R and hexagonal bolt, type SKS 10x110.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6357516
Type	TPB 100 A2
Description 1	Trapezoidal fastening
Manufacturer	OBO
Dimension	100x116
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	9.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4829 kg CO2e / 1 Piece


Technical data sheet

Ceiling bracket, trapezoidal A2

Item number: 6357516



Dimensions

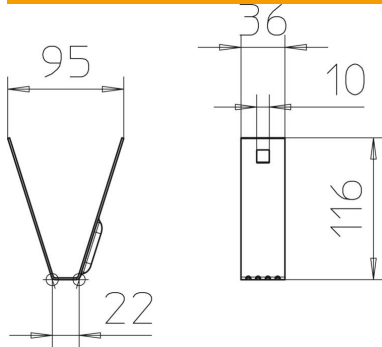

Length	36 mm
Width	100 mm
Height	116 mm

Technical data

F in kN	0.8 kN
Maintain electrical functions	no
Suitable for metric threaded rod	10
Material thickness	1.5 mm
ROHS-conformant	yes
Rustproof steel, pickled	yes
Hinged	no
Adjustable	yes