

Technical data sheet

Trapezoidal fastening A2

Item number: 6357524



Trapezoidal fastening for suspending cable support systems from standard trapezoidal ceilings. Trapezoidal profile width up to 165 mm. Mounting with hexagonal screw type SKS 10x110 minimum or SKS 10x190 maximum, depending on the trapezoidal profile width. Fastening material must be ordered separately.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6357524
Type	TPB 180 A2
Description 1	Trapezoidal fastening
Manufacturer	OBO
Dimension	180x182
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	11.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,8762 kg CO2e / 1 Piece


Technical data sheet

Trapezoidal fastening A2

Item number: 6357524



Dimensions

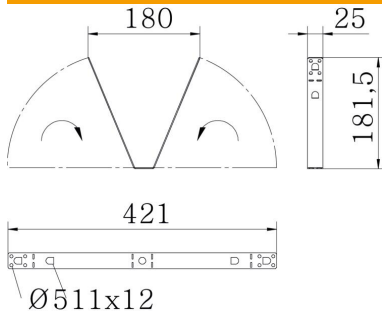

Length	25 mm
Width	180 mm
Height	182 mm

Technical data

F in kN	0.8 kN
Maintain electrical functions	no
Suitable for metric threaded rod	10
Suitable for mesh cable tray	yes
Suitable for cable ladder	yes
Suitable for cable tray	yes
Material thickness	1.5 mm
Rustproof steel, pickled	yes
Hinged	no
Adjustable	yes