


Technical data sheet

Central hanger for cable tray, side height 35 mm

Item number: 6358690



Centre suspension for cable trays with rolled side rail of side height 35 mm. The centre suspension possesses a rotatable M10 threaded sleeve. When filling, ensure an even distribution of the load (avoid one-sided filling).

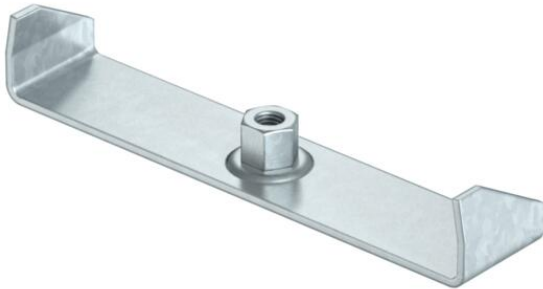


St	Steel
FS	Strip galvanised

Master data

Item number	6358690
Type	MAH 35 100 FS
Description 1	Centre suspension
Description 2	for cable tray
Manufacturer	OBO
Dimension	B100mm
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	9.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3858 kg CO2e / 1 Piece

Dimensions

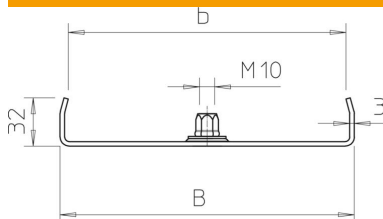

Length	40 mm
Width	100 mm
Width	4 in
Height	32 mm
Dimension B	95 mm
Dimension b	84 mm

Technical data sheet

Central hanger for cable tray, side height 35 mm

Item number: 6358690



Technical data

Version for	Suspended
F in kN	1.3 kN
Maintain electrical functions	no
for width max.	100 mm
for width min.	100
Suitable for metric threaded rod	10
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for tray/ladder width	100 mm
Hole diameter	10.5 mm
ROHS-conformant	yes
Adjustable	no