


Technical data sheet

Angle profile WP40/65 A2

Item number: 6373062

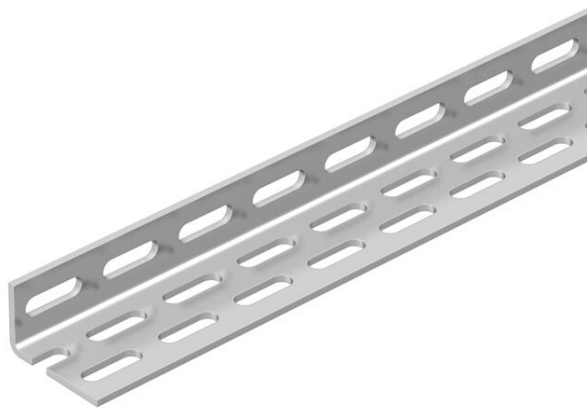

Perforated angle profile for creation of special support structures.
The angle profile can be used to create pendant suspensions.




A2	Stainless steel
2B	Bright, treated

Master data

Item number	6373062
Type	WP 40 65 5000 A2
Description 1	Angle profile
Description 2	perforated
Manufacturer	OBO
Dimension	40x65x5000
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	5
Unit of quantity	Metre
Weight	241.6 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	14,7267 kg CO2e / 1 Meter

Dimensions

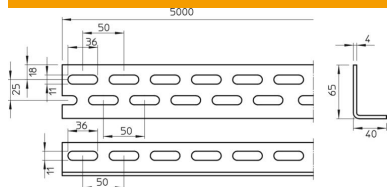

Length	5,000 mm
Width	65 mm
Height	40 mm
Plate thickness	4 mm

Technical data sheet

Angle profile WP40/65 A2

Item number: 6373062



Technical data

Breakable	no
Type of perforation	2 sides perforated
Version for	Single profile
Maintain electrical functions	no
With toothing	no
Mounting perforation in base	yes
Profile shape	L profile
ROHS-conformant	yes
Side perforation	yes