

Technical data sheet

Angle profile WP30/35

Item number: 6373100



Perforated angle profile for creation of special support structures.
The angle profile can be used to create pendant suspensions.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6373100
Type	WP 30 35 2000 FT
Description 1	Angle profile
Description 2	perforated
Manufacturer	OBO
Dimension	30x35x2000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	257 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	5,6741 kg CO2e / 1 Piece


Technical data sheet

Angle profile WP30/35

Item number: 6373100



Dimensions

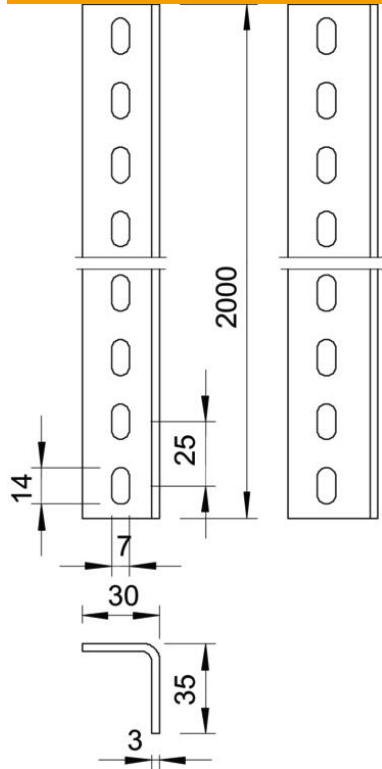

Length	2,000 mm
Width	35 mm
Height	30 mm
Plate thickness	3 mm

Technical data

Breakable	no
Type of perforation	2 sides perforated
Version for	Single profile
Maintain electrical functions	no
With tothing	no
Mounting perforation in base	yes
Profile shape	L profile
ROHS-conformant	yes
Side perforation	yes
Static value A	1.38 cm ²
Static value Iy	1.82 cm ⁴
Static value Iz	1.29 cm ⁴
Static value Wy	0.75 cm ³
Static value Wz	0.59 cm ³