


Technical data sheet

Angle profile WP40/50

Item number: 6373200



Perforated angle profile for the creation of special support structures.
The angle profile can be used to create pendant suspensions.

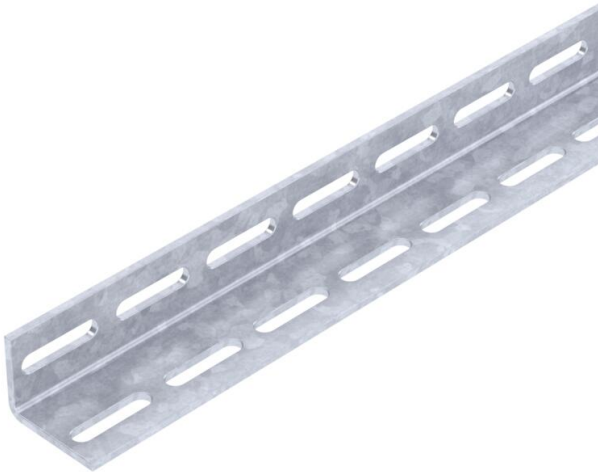

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6373200
Type	WP 40 50 3000 FT
Description 1	Angle profile
Description 2	perforated
Manufacturer	OBO
Dimension	40x50x3000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3
Unit of quantity	Metre
Weight	224 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	5,9935 kg CO2e / 1 Meter


Technical data sheet

Angle profile WP40/50

Item number: 6373200



Dimensions

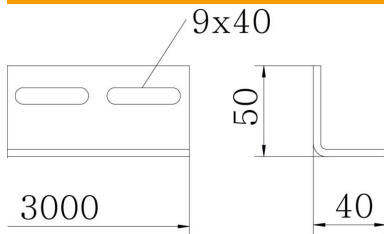

Length	3,000 mm
Width	50 mm
Height	40 mm
Plate thickness	4 mm

Technical data

Breakable	no
Type of perforation	2 sides perforated
Version for	Single profile
Maintain electrical functions	no
With toothings	no
Mounting perforation in base	yes
Profile shape	L profile
ROHS-conformant	yes
Side perforation	yes