

Technical data sheet

Truss-head bolt with flange nut F

Item number: 6406122



Truss-head bolt with square neck including flange nut.
For example, for use in longitudinal hole 7 x 20 mm or 7 x 32 mm.




St	Steel
F	Hot galvanised

Master data

Item number	6406122
Type	FRSB 6x12 F
Description 1	Truss-head bolt
Description 2	with combination nut
Manufacturer	OBO
Dimension	M6x12
Colour	zinc
Material	Steel
Surface	Hot galvanised
Surface standard	DIN 267, Teil 10
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.812 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0184 kg CO2e / 1 Piece

Dimensions

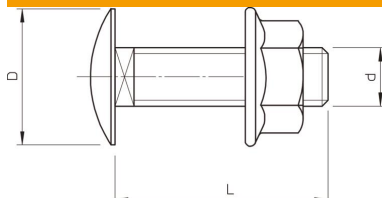

Length	12 mm
Dimension D	13.5 mm
Dimension d	6 mm
Dimension L	12 mm

Technical data sheet

Truss-head bolt with flange nut F

Item number: 6406122



Technical data

Resistance grade	5.6
Thread metric	6
Thread type	Metric
Head shape	Flat round head with square
With flange	no
With nut	yes
With washer	no
WAF	10
Screw system	Miscellaneous
Self-locking	no
Full thread	yes
Left thread	no