

Technical data sheet

Truss-head bolt with combination nut G

Item number: 6406130



Hot galvanised truss-head bolt with square neck including electrogalvanised combination nut.
For universal fastening of construction components. Permitted use of the article only in dry atmospheres.




St	Steel
G	Electrogalvanised

Master data

Item number	6406130
Type	FRSB 6x12 G
Description 1	Truss-head bolt
Description 2	with combination nut
Manufacturer	OBO
Dimension	M6x12
Colour	zinc
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.804 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0169 kg CO2e / 1 Piece

Dimensions

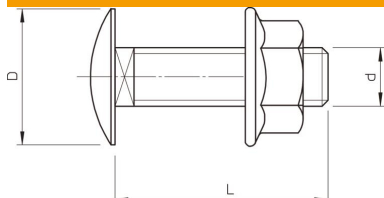

Length	12 mm
Dimension D	13.5 mm
Dimension d	6 mm
Dimension L	12 mm

Technical data sheet

Truss-head bolt with combination nut G

Item number: 6406130



Technical data

Resistance grade	5.6
Thread metric	6
Thread type	Metric
Head shape	Flat round head with square
With flange	no
With nut	yes
With washer	no
WAF	10
Screw system	Miscellaneous
Self-locking	no
Full thread	yes
Left thread	no