

Technical data sheet

Truss-head bolt with nut and washer A2

Item number: 6406718



Truss-head bolt with square neck including hexagonal nut and washer.




A2 Stainless steel

2B Bright, treated

Master data

Item number	6406718
Type	FRS 10x25 A2
Description 1	Truss-head bolt
Description 2	with washer and nut
Manufacturer	OBO
Dimension	M10x25
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	3.905 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1917 kg CO2e / 1 Piece

Dimensions

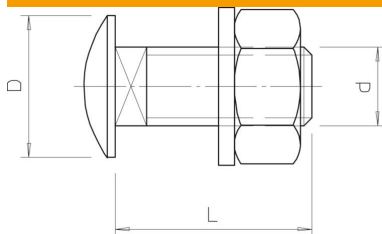

Length	25 mm
Dimension D	24 mm
Dimension d	10 mm
Dimension L	25 mm

Technical data sheet

Truss-head bolt with nut and washer A2

Item number: 6406718



Technical data

Resistance grade	A2-70
Thread metric	10
Thread type	Metric
Head shape	Flat round head with square
With flange	no
With nut	yes
With washer	yes
ROHS-conformant	yes
WAF	17
Screw system	Miscellaneous
Self-locking	no
Full thread	yes
Left thread	no