


Technical data sheet

Truss-head bolt with nut and washer F

Item number: 6407536

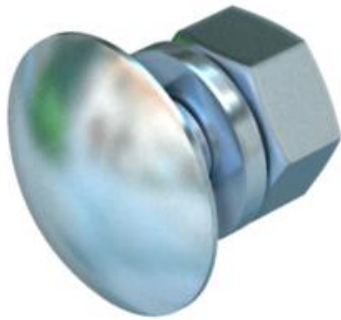

Truss-head bolt with square neck including hexagonal nut and washer.
The truss-head bolt can be used in combination with hot-dip and double-dip galvanised articles.



St

Steel


F

Hot galvanised

Master data

Item number	6407536
Type	FRS 10x25 TPS F
Description 1	Truss-head bolt
Description 2	for TPS + washer + nut
Manufacturer	OBO
Dimension	M10x25
Colour	zinc
Material	Steel
Surface	Hot galvanised
Surface standard	DIN 267, Teil 10
Smallest sales unit	50
Unit of quantity	Piece
Weight	4.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,077 kg CO2e / 1 Piece

Dimensions

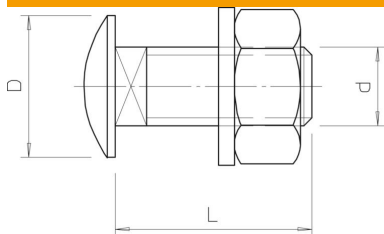

Length	25 mm
Dimension D	18 mm
Dimension d	10 mm
Dimension L	25 mm

Technical data sheet

Truss-head bolt with nut and washer F

Item number: 6407536



Technical data

Resistance grade	5.6
Thread metric	10
Thread type	Metric
Head shape	Flat round head with square
With flange	no
With nut	yes
With washer	yes
ROHS-conformant	yes
WAF	17
Screw system	Miscellaneous
Self-locking	no
Full thread	yes
Left thread	no