

Technical data sheet

Truss-head bolt with nut and washer A2

Item number: 6407537



Truss-head bolt with square neck. With washer and hexagonal nut.
The truss-head bolt can be used in combination with hot-dip and double-dip galvanised articles.




A2 Stainless steel

2B Bright, treated

Master data

Item number	6407537
Type	FRS 10x25 TPS A2
Description 1	Truss-head bolt
Description 2	for TPS + washer + nut
Manufacturer	OBO
Dimension	M10x25
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2023 kg CO2e / 1 Piece

Dimensions

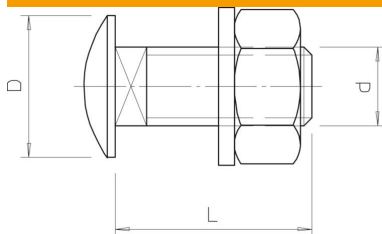

Length	25 mm
Dimension D	18 mm
Dimension d	10 mm
Dimension L	25 mm

Technical data sheet

Truss-head bolt with nut and washer A2

Item number: 6407537



Technical data

Resistance grade	A2-70
Thread metric	10
Thread type	Metric
Head shape	Flat round head with square
With flange	no
With nut	yes
With washer	yes
ROHS-conformant	yes
Screw system	Miscellaneous
Self-locking	no
Full thread	yes
Left thread	no