

Technical data sheet

Spacer A2

Item number: 6416448



Spacer for use in US 3 supports. The spacer increases the stability of the U-profile and prevents deformation of the support when tightening continuous hexagon bolts.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6416448
Type	DSK 25 A2
Description 1	Spacer
Description 2	for use in US 3 support
Manufacturer	OBO
Dimension	46x40x22,5
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	7.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3936 kg CO2e / 1 Piece


Technical data sheet

Spacer A2


Item number: 6416448



Dimensions

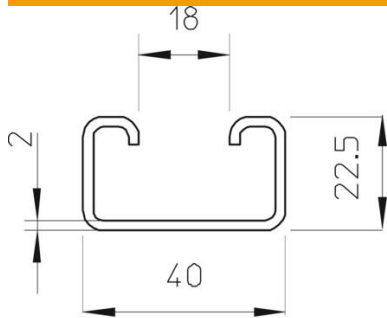

Dimension	46 x 40 x 22,5
Length	40 mm
Width	45 mm
Height	22.5 mm

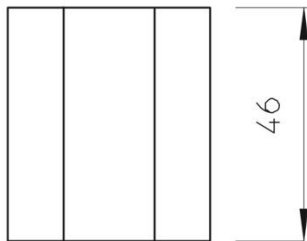

Technical data

Suitable for profile shapes	U profile
With screw accessories	no
ROHS-conformant	yes