


Technical data sheet

Hexagonal bolt M12 F

Item number: 6418287



Hexagonal bolt for universal fastening of construction components. With hexagonal nut and 2 washers.

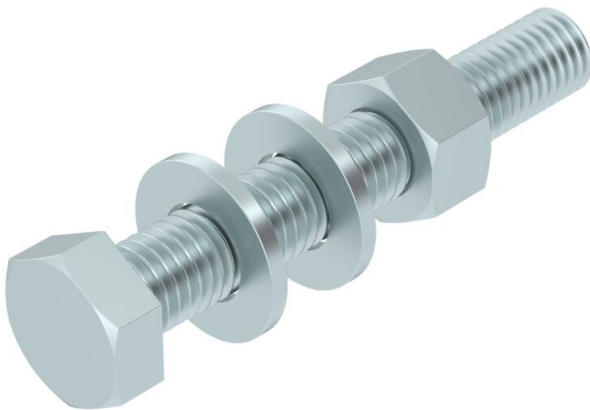

St	Steel
F	Hot galvanised

Master data

Item number	6418287
Type	SKS 12x80 F
Description 1	Hexagonal screw
Description 2	with nut and washers
Manufacturer	OBO
Dimension	M12x80
Colour	zinc
Material	Steel
Surface	Hot galvanised
Surface standard	DIN 267, Teil 10
Smallest sales unit	20
Unit of quantity	Piece
Weight	10 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2559 kg CO2e / 1 Piece


Technical data sheet

Hexagonal bolt M12 F

Item number: 6418287



Dimensions

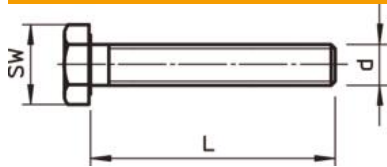

Length	80 mm
Dimension d	0.47 in
Dimension d	12 mm
Dimension L	3.14 in
Dimension L	80 mm

Technical data

Resistance grade	8.8
Thread	M 12 x 80
Thread metric	12
Thread type	Metric
Thread length	80 mm
Thread increase	1.75 mm
Head shape	Hexagonal
With flange	no
With nut	yes
With washer	yes
ROHS-conformant	yes
WAF	19
Screw system	Hexagonal
Self-locking	no
Full thread	yes
Left thread	no