


Technical data sheet

Wall bracket, variable AWV FT

Item number: 6419534



Variable wall bracket for fixing to sloping or vaulted walls.
Usable bracket length dependent on adjustment angle. The largest possible adjustment angle is 30°.

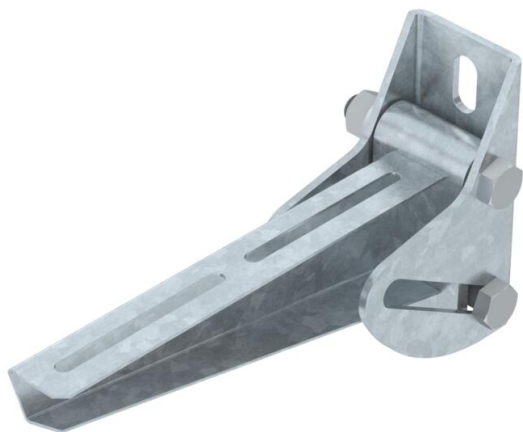

St

Steel

FT

Hot-dip galvanised

Master data

Item number	6419534
Type	AWV 21 FT
Description 1	Wall bracket, variable
Manufacturer	OBO
Dimension	B210mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	129 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,8735 kg CO2e / 1 Piece


Technical data sheet

Wall bracket, variable AWV FT

Item number: 6419534



Dimensions

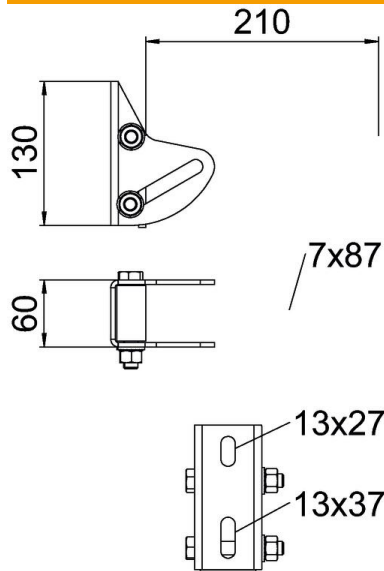

Length	60 mm
Width	210 mm
Height	130 mm
Dimension A	60 mm
Dimension B	210 mm
Dimension H	130 mm

Technical data

Version for	Wall brackets
F in kN	0.9 kN
Maintain electrical functions	no
for width max.	90 mm
for width min.	60
Hole diameter	13 mm
ROHS-conformant	yes
Rustproof steel, pickled	no