

Technical data sheet


Wall and support bracket AW 15



Item number: 6420912

Chalfant Item Nb.

Wall and support bracket with welded head plate and two fastening holes.
The double-perforated bracket offers the special option of double anchoring on
lightweight partitions and light masonry.

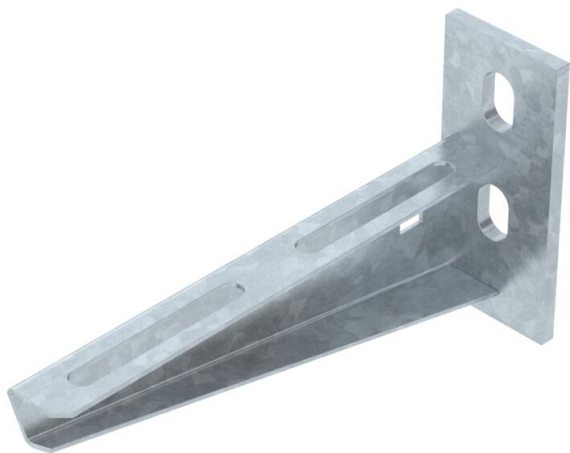

- St

Steel
- FT

Hot-dip galvanized

Master data		
Type	AW 15 16 FT 2L	
Manufacturer	OBO	
Colour	zinc	
Material	Steel	
Surface	Hot-dip galvanized	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	1	
Unit of quantity	Units	
Weight	20 kg	
Weight unit	kg/100 pairs	

Technical data sheet


Wall and support bracket AW 15



Item number: 6420912

Chalfant Item Nb.

Dimensions

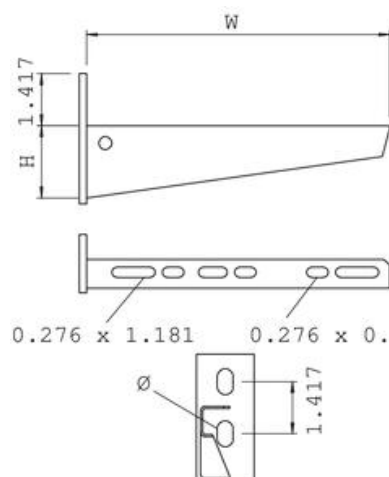


Length	40 mm
Width	160 mm
Width	6 in
Height	90 mm
Height	2.12 in
Dimension A	40 mm
Dimension B	160 mm
Dimension H	90 mm

Features/properties/dimensions

Version	Wall and support bracket
F in kN	1.5 kN
Maintain electrical functions	no
Hole diameter	11 mm
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm

Loads

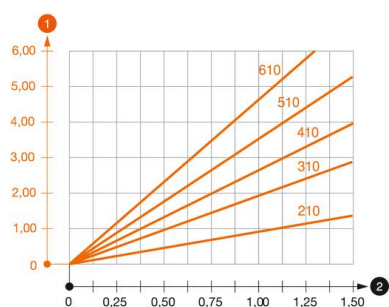

Load diagram, bracket, type AW 15

- 1 Bending of the bracket tip at permitted bracket load
- 2 Permitted bracket load in kN without man load
- Load curve with bracket lengths in mm