


# Technical data sheet

## Cross-over 60/200 A4

Item number: 7027522



Cross-over for the creation of a horizontal branch, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

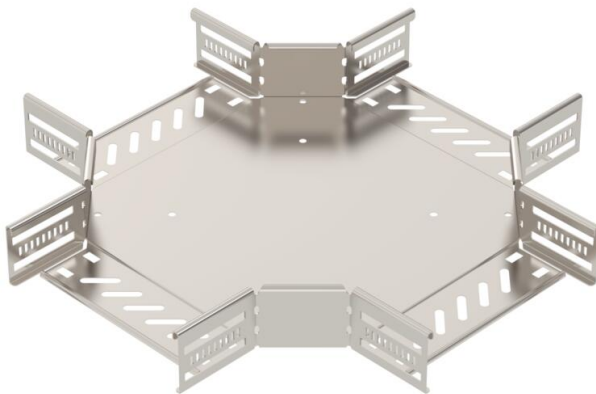

|    |                 |
|----|-----------------|
| A4 | Stainless steel |
| 2B | Bright, treated |

### Master data

|                                    |                           |
|------------------------------------|---------------------------|
| Item number                        | 7027522                   |
| Type                               | RK 620 A4                 |
| Description 1                      | Cross over                |
| Description 2                      | for cable tray            |
| Manufacturer                       | OBO                       |
| Dimension                          | 60x200                    |
| Colour                             | stainless steel           |
| Material                           | Stainless steel 1.4571    |
| Surface                            | Bright, treated           |
| Surface standard                   |                           |
| Smallest sales unit                | 1                         |
| Unit of quantity                   | Piece                     |
| Weight                             | 129.4 kg                  |
| Weight unit                        | kg/100 pc.                |
| CO2 Footprint (GWP) Cradle-to-Gate | 12,2096 kg CO2e / 1 Piece |


# Technical data sheet

## Cross-over 60/200 A4

Item number: 7027522



### Dimensions

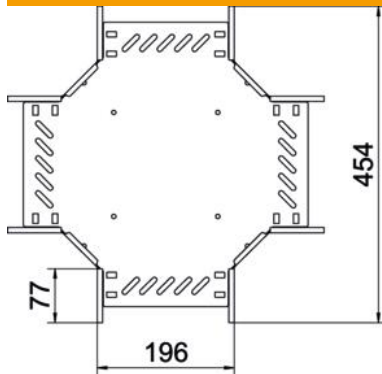

|                 |        |
|-----------------|--------|
| Width           | 200 mm |
| Height          | 60 mm  |
| Plate thickness | 0.8 mm |
| Dimension B     | 200 mm |

### Technical data

|                                         |                      |
|-----------------------------------------|----------------------|
| Connector version                       | Integrated connector |
| Maintain electrical functions           | yes                  |
| Material thickness, floor plate         | 0.8 mm               |
| NATO hole pattern                       | no                   |
| ROHS-conformant                         | yes                  |
| Rustproof steel, pickled                | no                   |
| Permitted temperature range, max.       | 120 °C               |
| Permitted temperature range, min.       | -20 °C               |
| Wide-span version                       | no                   |
| Type of connector, cable support system | Screwed              |
| Recommended quantity of bolts           | 24 St.               |
| Rail thickness                          | 1.25 mm              |