

# Technical data sheet

## Cover, cross-over FS

Item number: 7027804



Cover for cross-over fitting for lockable and screw-on cable trays in indoor areas, to protect cables against damage and soiling. Fastening through attachment of the section cover. Suitable for all side heights.  
The cover can be used with fittings of all side heights.



St

Steel

FS

Strip galvanised

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 7027804                  |
| Type                               | RKD 300 FS               |
| Description 1                      | Cover                    |
| Description 2                      | for cross-over           |
| Manufacturer                       | OBO                      |
| Dimension                          | B300mm                   |
| Colour                             | zinc                     |
| Material                           | Steel                    |
| Surface                            | Strip galvanised         |
| Surface standard                   | DIN EN 10346             |
| Smallest sales unit                | 1                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 98 kg                    |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 3,5754 kg CO2e / 1 Piece |


# Technical data sheet

## Cover, cross-over FS

Item number: 7027804



### Dimensions

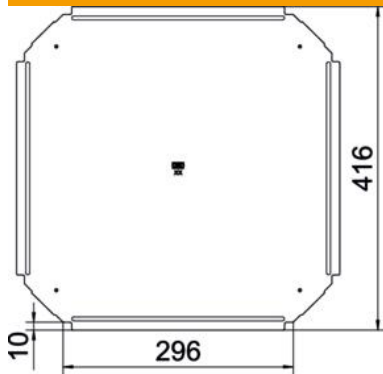

|                 |         |
|-----------------|---------|
| Width           | 300 mm  |
| Plate thickness | 0.75 mm |
| Dimension B     | 300 mm  |

### Technical data

|                                   |        |
|-----------------------------------|--------|
| Number of turn buckles            | 0 St.  |
| Fastening type                    | On top |
| Suitable for cable ladder         | no     |
| Suitable for cable tray           | yes    |
| Rustproof steel, pickled          | no     |
| Permitted temperature range, max. | 120 °C |
| Permitted temperature range, min. | -20 °C |