

Technical data sheet

Cover, cross-over 200 A2

Item number: 7027862



Cover for cross-over fitting for lockable and screw-on cable trays in indoor and outdoor areas, to protect cables against damage and soiling. Fastening through attachment of the section cover. Suitable for all side heights. The cover can be used with fittings of all side heights.



A2 Stainless steel

2B Bright, treated

Master data

Item number	7027862
Type	RKD 200 A2
Description 1	Cover
Description 2	for cross-over
Manufacturer	OBO
Dimension	B200mm
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	55 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,9774 kg CO2e / 1 Piece


Technical data sheet

Cover, cross-over 200 A2

Item number: 7027862



Dimensions

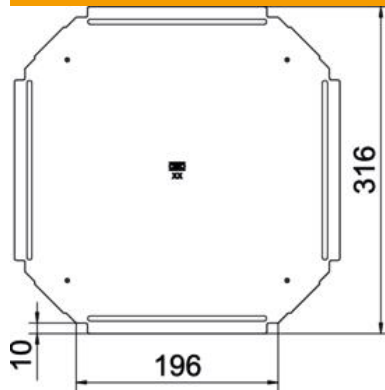

Width	200 mm
Plate thickness	0.75 mm
Dimension B	200 mm

Technical data

Number of turn buckles	0 St.
Fastening type	On top
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C