


Technical data sheet

Adjustable connector FT

Item number: 7082126



Adjustable connector for cable trays with a side height of 35 mm.
Including appropriate fastening material.

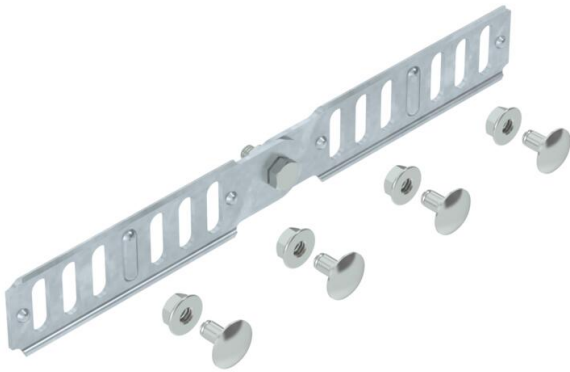

St	Steel
FT	Hot-dip galvanised

Master data

Item number	7082126
Type	RGV 35 FT
Description 1	Adjustable connector
Description 2	for cable tray
Manufacturer	OBO
Dimension	35x240
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	11 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3666 kg CO2e / 1 Piece


Technical data sheet

Adjustable connector FT

Item number: 7082126



Dimensions

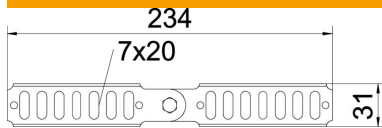

Dimension	234 x 31
Length	234 mm
Width	23 mm
Height	35 mm
Height	1 in
Plate thickness	2 mm

Technical data

Version for	Straight connector
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	35 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	yes
Rustproof steel, pickled	no
Connection type	Screw connector