


Technical data sheet

Adjustable connector 60 A2

Item number: 7082258



Adjustable connector for cable trays with a side height of 60 mm.
Including appropriate fastening material.

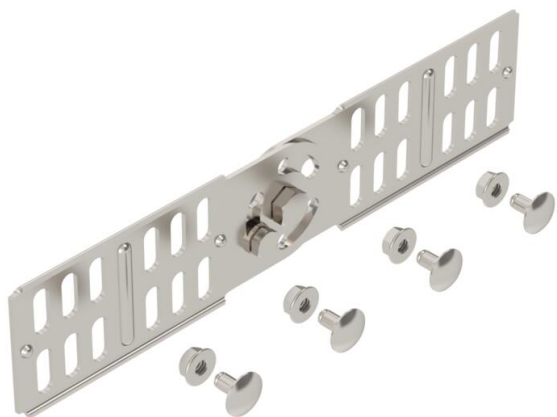

A2	Stainless steel
2B	Bright, treated

Master data

Item number	7082258
Type	RGV 60 A2
Description 1	Adjustable connector
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x260
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	25.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,6653 kg CO2e / 1 Piece


Technical data sheet

Adjustable connector 60 A2

Item number: 7082258



Dimensions

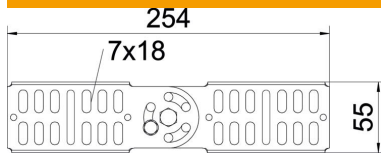

Dimension	254 x 56
Length	254 mm
Width	16 mm
Height	60 mm
Height	2 in
Plate thickness	2 mm

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	yes
Connection type	Screw connector