


Technical data sheet

Reducer/stop-end 60 A2

Item number: 7109814

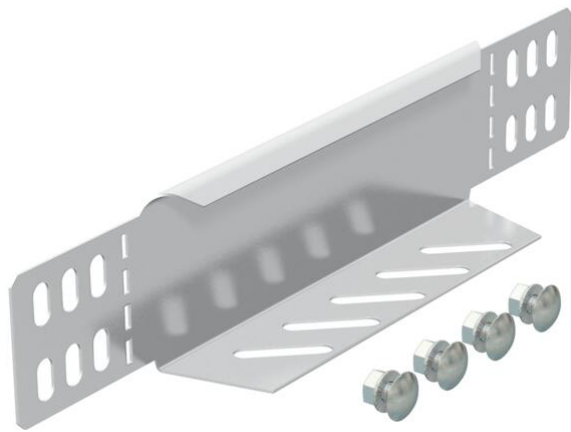

Reducer/stop-end plate for cable trays with side height 60 mm.
From a width of 150 mm, a perforated lower flange is available.

Including appropriate fastening material.




A2 Stainless steel

2B Bright, treated

Master data

Item number	7109814
Type	RWEB 610 A2
Description 1	Reducer profile/end closure
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x100
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	12.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7817 kg CO2e / 1 Piece

Dimensions

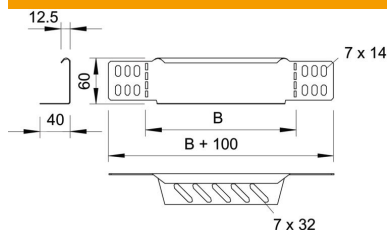

Width	100 mm
Width	4 in
Height	60 mm
Height	2 in
Plate thickness	1 mm
Dimension B	100 mm

Technical data sheet

Reducer/stop-end 60 A2

Item number: 7109814



Technical data

Maintain electrical functions	no
Rustproof steel, pickled	no