

Technical data sheet


Reducer/stop-end 60 A4

Item number: 7109951



Reducer and end closure plate for cable trays with side height 60 mm.
From a width of 150 mm, a perforated lower flange is available.

Including appropriate fastening material.

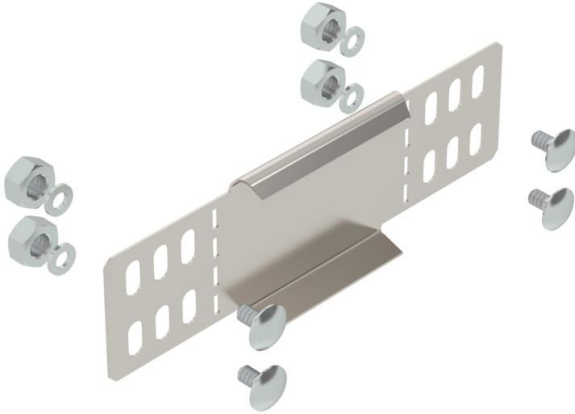

A4 Stainless steel

2B Bright, treated

Master data

Item number	7109951
Type	RWEB 610 A4
Description 1	Reducer profile/end closure
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x100
Colour	stainless steel
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	13.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,7629 kg CO2e / 1 Piece


Technical data sheet

Reducer/stop-end 60 A4

Item number: 7109951



Dimensions

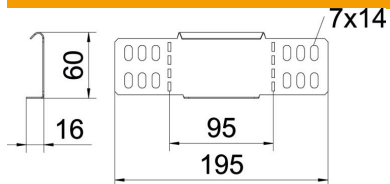

Width	100 mm
Height	60 mm
Height	2 in
Plate thickness	1 mm
Dimension B	95 mm

Technical data

Connector version	Integrated connector
Maintain electrical functions	no
ROHS-conformant	yes
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no