

Technical data sheet

PYROPLUG® MagicBox, four-sided, interior height 60 mm

Item number: 7204008



Fire protection box as an insulation system, made of two-part stainless steel housing with intumescent fire protection inlays. Can be used in walls and ceilings. Quick mounting through the releasable Magic connection. Interior can be fully assigned with installations. For interior application. Closure of the residual openings with PYROSIT® NG fire protection foam, particularly simple for difficult geometries. CE-labelled construction product with general type approval. Fire resistance class EI90 (fire-resistant). Including graphite strip.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	7204008
Type	PMB 630-4 A2
Description 1	Fire Protection Box 4-sided
Description 2	with intumescent inlays
Available from	04.10.2022
Manufacturer	OBO
Dimension	300x323x130
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	432.8 kg
Weight unit	kg/100 pc.


Technical data sheet

PYROPLUG® MagicBox, four-sided, interior height 60 mm

Item number: 7204008



Dimensions

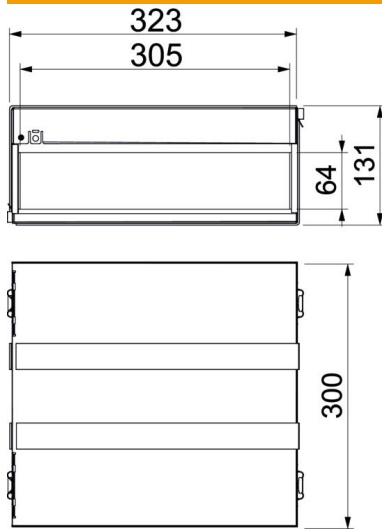

Length	300 mm
Width	323 mm
Height	131 mm
Dimension d	305 mm
Dimension d min.	323 mm

Technical data

Fire protection version	Box body
Shape	Rectangular
Accessories required	yes
Internal height	64 mm
Internal width	305 mm