

Technical data sheet

Internal corner, duct height 40 mm, pure white

Item number: 7218052



Internal corner with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroassignment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



St Steel

P Powder-coated

Master data

Item number	7218052
Type	PLM IC 0410 RW
Description 1	Internal corner
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	290x100x290
Colour	Pure white; RAL 9010
Material	Steel
Surface	Powder-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	116 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,1436 kg CO2e / 1 Piece


Technical data sheet

Internal corner, duct height 40 mm, pure white

Item number: 7218052



Dimensions

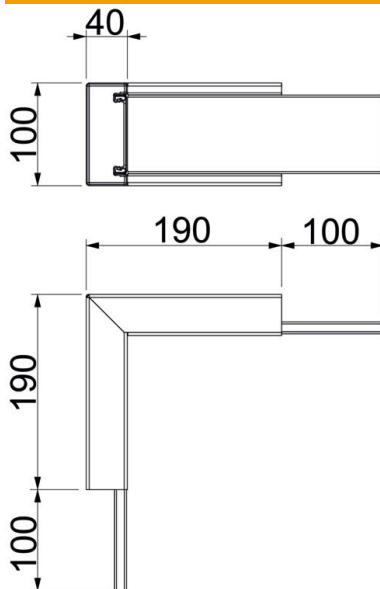

Dimension A	190 mm
Dimension B	100 mm
Dimension H	40 mm

Technical data

Number of flammable sides	4
Cover fastening	Miscellaneous
With perforation	yes
Usable cross-section	1780 mm ²
ROHS-conformant	yes
Partitions possible	no
Jacketing	Steel
Angle of the bend	90 °