

Technical data sheet

Flat angle, duct height 80 mm, FS

Item number: 7218066



Flat angle with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroassignment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



St

Steel

FS

Strip galvanised

Master data

Item number	7218066
Type	PLM FA 0810 FS
Description 1	Flat angle
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	350x350x80
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	166.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	6,2329 kg CO2e / 1 Piece


Technical data sheet

Flat angle, duct height 80 mm, FS

Item number: 7218066



Dimensions

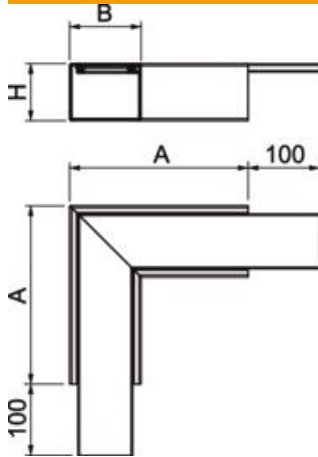

Dimension A	250 mm
Dimension B	100 mm
Dimension H	80 mm

Technical data

Number of flammable sides	4
Cover fastening	Miscellaneous
Classification EI - installation duct	90
With perforation	yes
Usable cross-section	5180 mm ²
ROHS-conformant	yes
Partitions possible	no
Jacketing	Steel
Angle of the bend	90 °