

Technical data sheet

Flat angle, duct height 120 mm, FS

Item number: 7218070



Flat angle with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroassignment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



St

Steel

FS

Strip galvanised

Master data

Item number	7218070
Type	PLM FA 1220 FS
Description 1	Flat angle
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	350x350x120
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	286.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	12,6263 kg CO2e / 1 Piece


Technical data sheet

Flat angle, duct height 120 mm, FS

Item number: 7218070



Dimensions

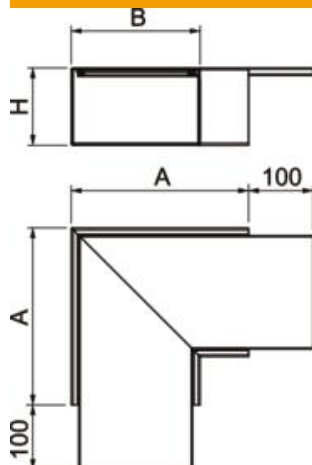

Dimension A	275 mm
Dimension B	200 mm
Dimension H	120 mm

Technical data

Number of flammable sides	4
Cover fastening	Miscellaneous
Classification EI – installation duct	90
With perforation	yes
Usable cross-section	18500 mm ²
ROHS-conformant	yes
Partitions possible	no
Jacketing	Steel
Angle of the bend	90 °