

Technical data sheet

Vertical bend, falling, duct height 120 mm, pure white

Item number: 7218112



45° vertical bend, falling version, with intumescent fire protection mesh for PYROLINE® Rapid PLM installation duct. Suitable for direct wall and ceiling mounting, mounting below system floors and on support systems. Tool-free joint mounting with PLM SI joint connector. The cover is snapped on without tools, allowing rapid inspection and retroassignment. The cover overhang allows offset cover mounting for continuous equipotential bonding of the entire duct section.



St Steel

P Powder-coated

Master data

Item number	7218112
Type	PLM BF 1220 RW
Description 1	Bend 45°, falling
Description 2	with fire protection mesh
Manufacturer	OBO
Dimension	498x200x215
Colour	Pure white; RAL 9010
Material	Steel
Surface	Powder-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	243 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,8147 kg CO2e / 1 Piece


Technical data sheet

Vertical bend, falling, duct height 120 mm, pure white

Item number: 7218112



Dimensions

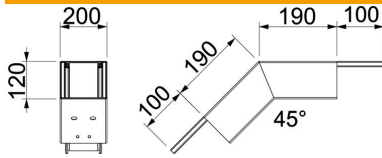

Dimension A	190 mm
Dimension B	200 mm
Dimension H	120 mm

Technical data

Number of flammable sides	4
Cover fastening	Miscellaneous
Classification EI – installation duct	90
With perforation	yes
Usable cross-section	18500 mm ²
ROHS-conformant	yes
Partitions possible	no
Jacketing	Steel
Angle of the bend	45 °