


Technical data sheet

Trunking end piece

Item number: 7403820



Ready-to-mount trunking end connection, consisting of a side wall and a height-adjustable side profile for universal installation on left or right.

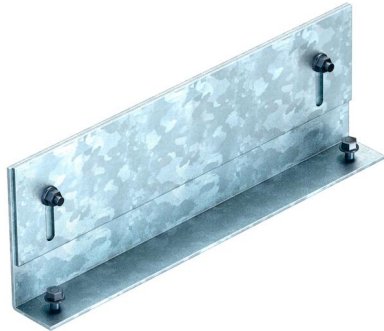

St

Steel


FS

Strip galvanised

Master data

Item number	7403820
Type	OKB ES 25085
Description 1	End cover
Description 2	for OKB
Manufacturer	OBO
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	52.85 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,3633 kg CO2e / 1 Piece

Dimensions

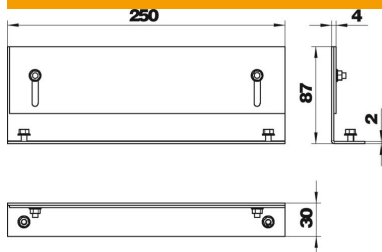

Width	250 mm
Height	93 mm
Dimension h	85 mm

Technical data sheet

Trunking end piece

Item number: 7403820



Technical data

Mounting opening cover	no
Floor plate	yes
Floor care	Dry
Cover fastening, locking	no
Seal installation option	no
Installation opening for on-floor tank	no
Decouplable	yes
Suitable for expansion joint	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for flushfloor, open underfloor trunking	yes
Suitable for screed-covered underfloor ducts	no
Mesh wall	no
Trunking height, max.	125 mm
Duct height, min.	85 mm
Minimum screed height	85
With connection opening	no
With equipotential bonding	no
With separating retainer	no
With overhang	yes
Mounting opening	Without
Height-adjustment range, min.	0 mm
Removable cover	yes
Separating retainer fastening	stecken
Separating retainer fastening	Plug