


Technical data sheet

T piece, without height adjustment units

Item number: 7403836



Ready-to-mount connection of a trunking unit with a brush bar and a trunking unit for cable laying, consisting of trunking bases, two lids, height-adjustable side profiles and brush bar arranged on the wall side for cable alignment. The scope of delivery contains two lid butt seals and two connectors. For height adjustment six levelling units are required.

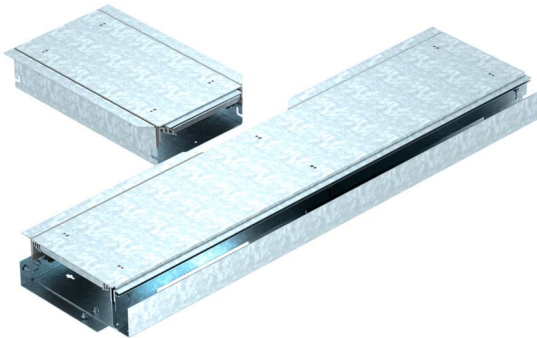

St	Steel
FS	Strip galvanised

Master data

Item number	7403836
Type	OKB TS 25085 ON
Description 1	T piece
Description 2	with brush bar
Manufacturer	OBO
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	1850 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	78,5261 kg CO2e / 1 Piece


Technical data sheet

T piece, without height adjustment units

Item number: 7403836



Dimensions

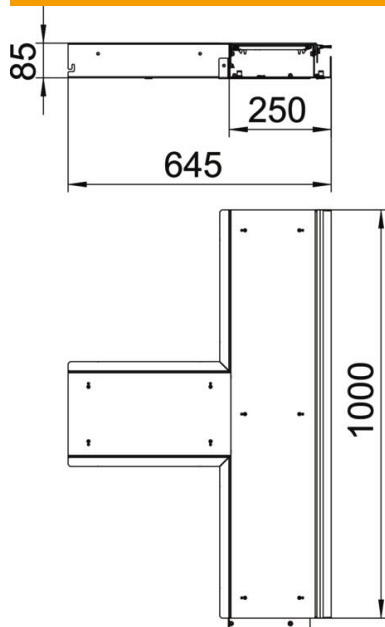

Length	1,000 mm
Width	250 mm
Height	93 mm
Dimension h	85 mm

Technical data

Mounting opening cover	no
Floor plate	yes
Floor care	Dry
Cover fastening, locking	no
Seal installation option	no
Installation opening for on-floor tank	no
Decouplable	yes
Function	Branch
Suitable for expansion joint	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for flushfloor, open underfloor trunking	yes
Suitable for screed-covered underfloor ducts	no
Minimum screed height	93
With connection opening	no
With equipotential bonding	no
With separating retainer	no
With overhang	yes
Height-adjustment range, min.	0 mm
Removable cover	yes
Separating retainer fastening	stecken
Separating retainer fastening	Plug