

Technical data sheet

Device support

Item number: 7403850



System fastening for universal supports in the trunking base.



- St** Steel
- FS** Strip galvanised

Master data	
Item number	7403850
Type	OKB IT
Description 1	Mounting box
Description 2	for OKB
Manufacturer	OBO
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	5.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2678 kg CO2e / 1 Piece


Technical data sheet

Device support

Item number: 7403850



Dimensions

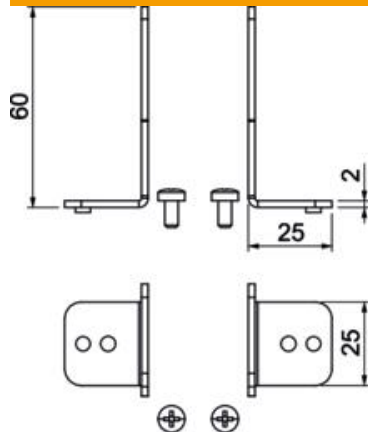

Length	25 mm
Width	25 mm
Height	60 mm

Technical data

Mounting opening cover	no
Type of accessory	Miscellaneous
Floor plate	no
Floor care	Dry
Cover fastening, locking	no
Seal installation option	no
Decouplable	no
Suitable for expansion joint	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for flushfloor, open underfloor trunking	yes
Suitable for screed-covered underfloor ducts	no
Minimum screed height	85
With connection opening	no
With equipotential bonding	no
With overhang	yes
Height-adjustment range, min.	0 mm
Removable cover	yes