

Technical data sheet

GES6 service outlet with locking slider

Item number: 7405321



Service outlet with locking slider for up to 9 individual Modul 45 devices in 3 UT3 universal supports, use in trunking systems and system floors for indoor use.

Floor covering recess in the hinged cover pre-adjusted to 5 mm, if necessary adjustable to 3, 8 or 10 mm.

Up to 6 installation devices with 50 mm central plate can be inserted.

Service outlet with locking slider, 3-compartment, for the installation of MT6 mounting support. Three type APMT2 cover plates can be installed.

Floor covering recess in the hinged cover pre-adjusted to 5 mm, if necessary adjustable to 3, 8 or 10 mm.



PA Polyamide

Master data

Item number	7405321
Type	GES6-2U10T 7011
Description 1	Service outlet
Description 2	for universal mounting
Manufacturer	OBO
Dimension	274x221x66
Colour	Iron grey; RAL 7011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	138 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,1226 kg CO2e / 1 Piece


Technical data sheet

GES6 service outlet with locking slider

Item number: 7405321



Dimensions

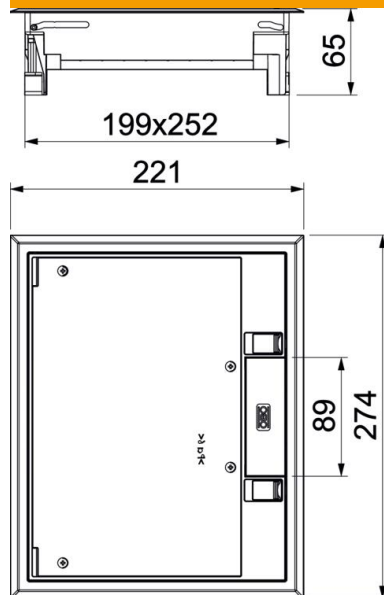

Length	221 mm
Width	274 mm
Height	65 mm

Technical data

Number of installable devices	9
Number of mounting boxes	3
Cover version	Rectangular
Cable outlet version	Swivellable cord outlet
Floor covering protection frame	yes
Floor care	Dry
Seal installation option	no
Screed height, min.	73 mm
Floor height, min.	73 mm
Suitable for raised floor installation	yes
Suitable for cavity floor installation	yes
Suitable for wet care	no
Suitable for underfloor box	250/350
Suitable for underfloor ducts	yes
Device support to accept mounting boxes	yes
Length of external dimensions	221 mm
Length of installation dimensions	201 mm
With floor covering recess	yes
Nominal size for device installation units	6
Frame version	Carpet protection frame
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK08
Heavy-duty version	no

Technical data sheet

GES6 service outlet with locking slider

Item number: 7405321



Technical data

Clamping range D, max.	75 mm
Clamping range D, min.	8 mm
Installation system type	UT3
Vertical load, large area	to 3,000 N
Vertical load, small area	to 2,000 N
Approvals	VDE
Opening mechanism	Locking slider
Floor covering thickness	5 mm
Floor covering thickness max.	10 mm