

Technical data sheet

Height adjustment unit RKNEV2

Item number: 7405815



For flushfloor height adjustment of the height adjustable cassette units and the OKB screed-flush trunking system. The VPE consists of 4 height adjustment units.
The following table shows the height-adjustment ranges of the height-adjustment units for the cassettes and the OKB trunking system. The stated height-adjustment ranges refer to the top edge of the raw floor to the top edge of the floor covering.



St

Steel

G

Electrogalvanised

Master data

Item number	7405815
Type	RK NEV2 110
Description 1	Height-adjustment unit
Description 2	for cassette and OKB
Manufacturer	OBO
Dimension	M8x110mm
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	1
Unit of quantity	Packaging unit
Weight	25.415 kg
Weight unit	kg/100 PUs
CO2 Footprint (GWP) Cradle-to-Gate	0,7442 kg CO2e / 4 Piece


Technical data sheet

Height adjustment unit RKNEV2

Item number: 7405815



Dimensions

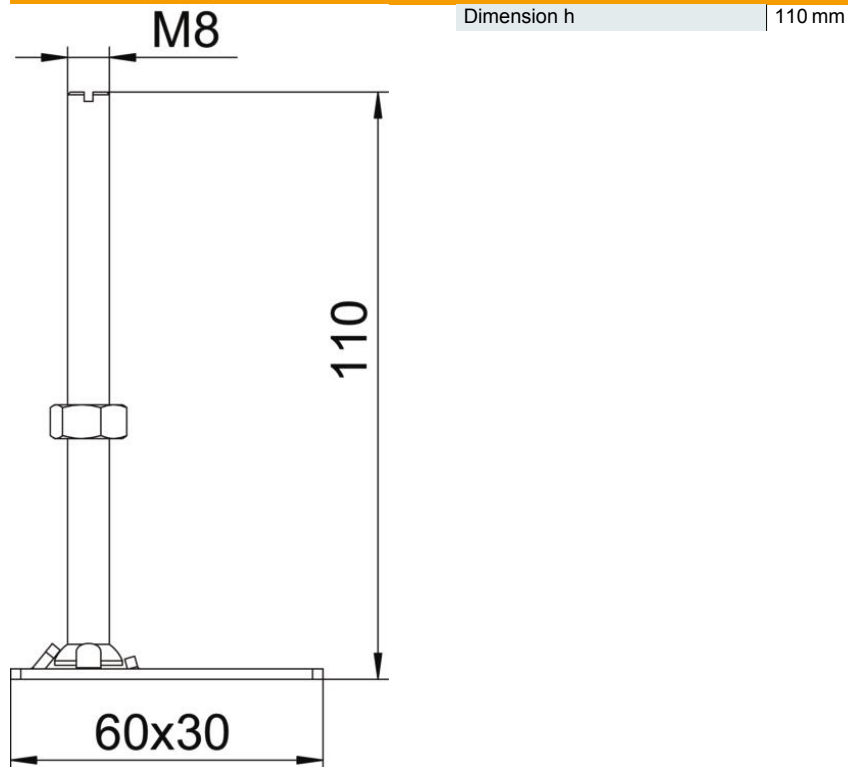

Technical data

Type of accessory	Miscellaneous
Height-adjustment range, max.	190 mm
Height-adjustment range, min.	140 mm
Suitable for ducts and trunking	yes
Suitable for cassettes	yes
With footfall sound insulation	no
Material of the foot	Metal